



Additif Catalogue



Embrayages

Juillet 2019

Nouveautés PL



SCHAEFFLER

**KAMAZ**

4

43255 B 5.9; (134kW)	01.03-	CUMMINS; B3.90-140 CIV, B5.9-140 CIV 1; ZF; S5-42	336 0044 10		
-------------------------	--------	---------------------------------------------------	-------------	--	--

NISSAN**ATLEON**

80.19 ISB4.5; (136kW)	10.06-	ISB4-6L; FSO 52068	636 3044 00		
		ISB5-4			
		ISB4-6L; FSO 52068	336 0036 10		
		ISB5-4			

RENAULT TRUCKS**C-Serie**

320P 320PK; 280P 280PK; 250FG P, PK; 320FG P, PK; 280FG P, PK; 250P 250PK DTI8-122HQ; DTI8-122HR; DTI8-122HS; (184-235kW)	01.13-	AT2412 E ATO2612 E AT2412 F ATO2412 F	143 0390 10		
------------------------------------------------------------------------------------------------------------------------------	--------	------------------------------------------------	-------------	--	--

D-Serie

26 P 250, 280, 320; 26 KP 250, 280, 320; 13 P 250, 280; 13 KP 250, 280; 16 KP 250, 280; 25 P 250, 280, 320; 18 P 250, 280, 320; 18 T 280, 320; 12 KP 250, 280; 14 P 250, 280; 14 KP 250, 280; 12 P 250, 280; 16 P 250, 280; 18 KP 250, 280, 320 DTI8-122HQ; DTI8-122HR; DTI8-122HS; (184-235kW)	01.13-	AT2412 E AT2412 F ATO2612 F	143 0390 10		
----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	--------	-----------------------------------	-------------	--	--

D-Series Access

18 ACCESS P 280, 320; 26 ACCESS P 280, 320 DTI8-122HR; DTI8-122HS; (206-235kW)	07.14-	AT2412 E AT2412 F ATO2612 F	143 0390 10		
-----------------------------------------------------------------------------------	--------	-----------------------------------	-------------	--	--

Kerax

370.18; 370.26; 370.32; 410.18; 410.26; 410.32 DXi 11; (272-302kW)	10.05-	AT2512 C ATO2512 C	143 0390 10		
-----------------------------------------------------------------------	--------	-----------------------	-------------	--	--

Maxity

150.35; 150.45 DXi 3; (110kW)	03.07-	6RT H; 150KG excl. Ⓞ	628 3362 00		
----------------------------------	--------	-------------------------	-------------	--	--

Premium 2

Distribution 240.18 D; Distribution 270.19, 280.26, 310.18, 310.26, 320.18, 320.26, 340.18, 340.19, 340.26; Distribution 280.18 D; Distribution 320.18 D; Lander 270.18, 270.19, 310.19, 310.26, 340.18, 340.19, 340.26 DXi 7; (177-247kW)	10.05-	AT2412 D	143 0390 10		
Distribution 370.18 D; Distribution 370.26, 380.18, 410.26; Distribution 410.18 D; Lander 380.19, 380.26, 380.32 DXi 11; (272-302kW)	10.05-	AT2412 C AT2412 D ATO2512 C ATO2512 D	143 0390 10		
Distribution 380.19, 380.26 DXi 11; (280kW)	10.06-	ZF; AT2412 C ZF; AT2412 D ZF; ATO2512 C ZF; ATO2512 D	143 0390 10		
Route 330.18 T; Route 380.18, 380.19, 380.26 DXi 11; (243-280kW)	10.05-	AT2412 C AT2412 D	143 0390 10		
Route 410.18, 410.24, 410.25, 410.26; Route 410.18 D DXi 11; (302kW)	10.05-	AT2412 C ATO2512 C	143 0390 10		

VOLVO**FE**

FE 240-18, 240-22, 240-26, 260-18, 260-26, 280-18, 280-22, 280-26, 300-18, 300-26, 320-18, 320-22, 320-26, 340-18, 340-26 D7E240; D7E280; D7E320; D7F240; D7F260; D7F300; D7F340; (177-250kW)	05.06-	AT2412 D	143 0390 10		
--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	--------	----------	-------------	--	--

FE II

FE 250-18, 250-26, 280-18, 280-26, 320-18, 320-26	05.12-	AT2412 E	143 0390 10		
---------------------------------------------------	--------	----------	-------------	--	--



VOLVO



VOLVO

FE II					
<ul style="list-style-type: none"> D8K250; D8K280; D8K320; (184-235kW) 	05.12-				
FE 280-18 <ul style="list-style-type: none"> D7E280; (206kW) 	05.12-	<ul style="list-style-type: none"> ZF; AT2412 E 		143 0390 10	
FM					
FM 300 <ul style="list-style-type: none"> D9A300; D9B300; (220-221kW) 	09.05-	<ul style="list-style-type: none"> AT2412 C AT2512 C 		143 0390 10	
FM 330, 370, 390, 410 <ul style="list-style-type: none"> D11B390; D11C330; D11C370; D11C410; D11K330; (243-302kW) 	09.05-	<ul style="list-style-type: none"> AT2412 D AT2612 D ATO2612 D 		143 0390 10	
FM 330 <ul style="list-style-type: none"> D11C330; D11K330; (243kW) 	09.05-	<ul style="list-style-type: none"> D11C330; AT2412 D D11C330; AT2612 D D11C330; ATO2612 D 		143 0390 10	
FM 340 <ul style="list-style-type: none"> D9A340; D9B340; (250kW) 	09.05-	<ul style="list-style-type: none"> AT2412 C AT2512 C ATO2512 C 		143 0390 10	
FM 370 <ul style="list-style-type: none"> D11C370; D11K370; (272kW) 	09.05-	<ul style="list-style-type: none"> D11C370; AT2412 D D11C370; AT2612 D D11C370; ATO2612 D 		143 0390 10	
FM 410 <ul style="list-style-type: none"> D11C410; D11K410; (302kW) 	09.05-	<ul style="list-style-type: none"> D11C410; AT2412 D D11C410; AT2612 D D11C410; ATO2612 D 		143 0390 10	
FMX					
330; 370; 410 <ul style="list-style-type: none"> D11C330; D11C370; D11C410; (243-302kW) 	04.10-	<ul style="list-style-type: none"> AT2412 D AT2612 D ATO2612 D 		143 0390 10	

IRISBUS



IRISBUS

CROSSWAY

12m 12.8m; 10.6m 12.8m, 12m (194-243kW)	06.06-	F4AE0682, F4AE0682L, F4AE3882A; ZF; 6S-1200 F4AE0682; ZF; 6S-1600	640 3116 00	140 0204 20 21 19 340 0086 10 500 0976 20
--------------------------------------------	--------	------------------------------------------------------------------------	-------------	--------------------------------------------------

KAVZ

AURORA

4235 ISBe 150; (110kW)	01.08-		336 0044 10	
---------------------------	--------	--	-------------	--

SETRA

Series 400

TopClass S 415 HDH; TopClass S 416 HDH; TopClass S 417 HDH; TopClass S 431 DT OM 457.944; OM 457.953; OM 457.961; OM 542.948; OM 542.966; OM 942.911; (260-370kW)	10.01-	A4100000025	343 0264 10	
----------------------------------------------------------------------------------------------------------------------------------------------------------------------	--------	-------------	-------------	--

VOLVO

7900

7900 ELECTRIC HYBRID; 7900 HYBRID D5K240; (176-177kW)	08.16-	I-Shift	143 0390 10	
----------------------------------------------------------	--------	---------	-------------	--

9500

9500 D8K320; D8K350; (235-258kW)	08.16-	AT2412 E AT2412 F	143 0390 10	
-------------------------------------	--------	----------------------	-------------	--

9700

9700 DH12E460; (338kW)	10.07-		143 0390 10	
---------------------------	--------	--	-------------	--

9900

9900 DH12E460; (338kW)	10.07-		143 0390 10	
---------------------------	--------	--	-------------	--

B 9

B 9 D9B260; D9B310; D9B360; (191-265kW)	09.05-	BM B9 R; AT2412 C	143 0390 10	
--------------------------------------------	--------	--------------------	-------------	--

B 11

B11R D11C370; D11K380; (272-280kW)	09.11-	D11C370; AT2412 C D11C370; AT2612 C D11C370; AT2812 C D11C370; AT02612 C D11C370; AT2412 D D11C370; AT2612 D D11C370; AT2812 D	143 0390 10	
---------------------------------------	--------	---------------------------------------------------------------------------------------------------------------------------------------------------------	-------------	--

B11R D11C330; D11C410; (243-302kW)	09.11-	AT2412 C AT2612 C AT2812 C AT02612 C AT2412 D AT2612 D AT2812 D	143 0390 10	
---------------------------------------	--------	-----------------------------------------------------------------------------------	-------------	--

B 12


B 12 D12D380; DH12D340; DH12E340; DH12E380; (250-280kW)	02.06-	BM B12 B; AT2412 C	143 0390 10	
------------------------------------------------------------	--------	---------------------	-------------	--

B 12 D12C420; D12D420; DH12E420; (309kW)	02.06-	BM B12 B/ R; AT2412 C	143 0390 10	
---------------------------------------------	--------	------------------------	-------------	--



143 0390 10	RENAULT TRUCKS	15
143 0390 10	VOLVO	15, 16, 18
336 0036 10	NISSAN	15
336 0044 10	KAMAZ	15
336 0044 10	KAVZ	18
343 0264 10	SETRA	18
628 3362 00	RENAULT TRUCKS	15
636 3044 00	NISSAN	15
640 3116 00	IRISBUS	18



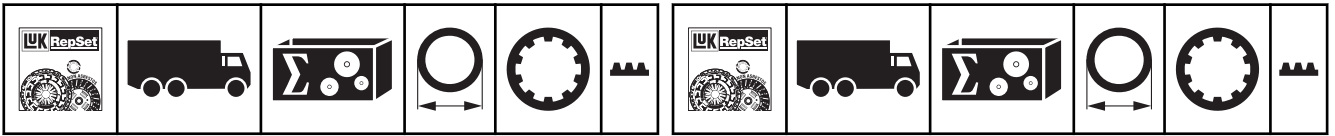

628 3362 00	RENAULT TRUCKS	128 0426 10	280 ZBFM							
		328 0841 10	280 TZFN	A10x23x29	10					
		500 0635 30								
640 3116 00	IRISBUS	140 0204 20	400 ZBFK							
		340 0086 10	395 TZFV	1 3/4	10					
		500 0976 20								



**2...**

20484461	VOLVO	143 0390 10
20806453	VOLVO	143 0390 10
21134336	VOLVO	143 0390 10
2296059	IRISBUS	640 3116 00

3...

30100-LA400	NISSAN	336 0036 10
30100-LA400	NISSAN	636 3044 00
30210-LA400	NISSAN	636 3044 00
30501-LA400	NISSAN	636 3044 00

5...

5010 556 020	IRISBUS	640 3116 00
5010 556 020	IRISBUS	140 0204 20
5010 556 200	IRISBUS	640 3116 00
5010 556 200	IRISBUS	140 0204 20

7...

74 20 812 086	RENAULT TRUCKS	143 0390 10
74 21 134 335	RENAULT TRUCKS	143 0390 10
74 85 120 143	RENAULT TRUCKS	628 3362 00
74 85 120 143	RENAULT TRUCKS	128 0426 10
74 85 129 222	RENAULT TRUCKS	628 3362 00
74 85 129 222	RENAULT TRUCKS	328 0841 10

8...

82 01 108 206	RENAULT TRUCKS	628 3362 00
82 01 108 206	RENAULT TRUCKS	500 0635 30
82 01 246 083	RENAULT TRUCKS	628 3362 00
82 01 246 083	RENAULT TRUCKS	500 0635 30
85003117	VOLVO	143 0390 10
85013742	VOLVO	143 0390 10
85019742	VOLVO	143 0390 10

