



Additif Catalogue



Embrayages

Octobre 2018

Nouveautés PL



SCHAEFFLER

MERCEDES-BENZ

					
--	--	--	--	--	--

MERCEDES-BENZ

LK/LN2

817; 917; 1117; 1317; 1517  675.046, 675.146, 676.001, 676.002, 676.003, 676.004, 676.006, 676.007, 676.008, 676.009, 676.012, 676.013, 676.014, 676.015, 676.016, 676.017, 676.018, 676.019, 676.022, 676.023, 676.024, 676.025, 676.026, 676.027, 676.028, 676.029, 676.032, 676.033, 676.034, 676.035, 676.036, 676.037, 676.038, 676.039, 676.040, 676.041, 676.042, 676.043, 676.045, 676.046, 676.047, 676.050, 676.051, 676.052, 676.053, 676.054, 676.055, 676.056, 676.057, 676.059, 676.060, 676.066, 676.067, 676.068, 676.069, 676.080, 676.081, 676.082, 676.083, 676.084, 676.085, 676.090, 676.112, 676.117, 676.142, 676.143, 676.144, 676.145, 676.146, 676.147, 676.148, 676.149, 676.182, 676.183, 676.184, 676.185, 676.195, 676.196, 676.197, 676.198, 676.201, 676.202, 676.203, 676.204, 676.206, 676.207, 676.208, 676.209, 676.212, 676.213, 676.214, 676.217, 676.218, 676.219, 676.222, 676.223, 676.224, 676.225, 676.226, 676.227, 676.228, 676.229, 676.232, 676.233, 676.234, 676.235, 676.236, 676.236.12, 676.237, 676.237.12, 676.238, 676.238.12, 676.239, 676.239.12, 676.250, 676.251, 676.252, 676.253, 676.254, 676.255, 676.256, 676.257, 676.258, 678.022, 678.023, 678.026, 678.028, 678.122, 678.126, 678.171, 678.172  OM 356.941; OM 356.944; OM 356.945; OM 356.946; OM 356.947; OM 356.951; OM 356.953; OM 356.959; OM 357.900; OM 357.901; OM 357.902; OM 357.903; OM 357.906; OM 357.907; OM 357.908; OM 357.909; OM 357.910; OM 357.916; OM 357.918; OM 357.961; OM 357.962; OM 357.963; OM 366.941; OM 366.942; OM 366.943; OM 366.944; OM 366.945; OM 366.946; OM 366.953; OM 366.962; OM 366.966; OM 366.967; OM 366.968; OM 366.970; OM 366.973; OM 366.974; OM 366.975; OM 366.976; OM 366.978; OM 366.979; (116-125kW)	01.84-12.98	SA24494 01	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1120  677.012, 677.013, 677.014, 677.015, 677.016, 677.017, 677.018, 677.019, 677.212, 677.213, 677.214, 677.216, 677.217, 677.218  OM 356.986; OM 356.992; OM 357.920; OM 357.927; OM 357.932; OM 366.988; (148-155kW)	01.84-12.98	 BM 677.012-015  BM 677.212-214	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1120  677.083, 677.183, 677.196  OM 356.994; OM 356.995; OM 356.996; OM 366.992; OM 366.994; (150-155kW)	02.87-12.98	 →5906887	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1120; 1320  677.032, 677.212, 677.232, 677.234, 677.235  OM 356.983; OM 366.962; OM 366.966; (125-177kW)	01.84-12.98		635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7



					
--	--	--	--	--	--

MERCEDES-BENZ
LK/LN2

1120  677.050, 677.051, 677.052, 677.053, 677.250, 677.251, 677.252, 677.253  OM 356.986; OM 357.920; OM 357.927; OM 357.932; OM 366.988; (148-155kW)	01.84-12.98	 BM 677.052/053/252/253	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1124  677.183, 677.184, 677.196, 677.197  OM 356.983; OM 356.989; OM 356.991; OM 357.943; OM 357.944; (177kW)	03.92-12.98	 BM 677.183/196;  →5906887	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1124  677.083, 677.084  OM 356.979; OM 356.983; OM 357.933; OM 357.942; (155-177kW)	03.92-12.98	 BM 677.083;  →5906887	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1320  677.032, 677.033, 677.034, 677.035, 677.036, 677.037, 677.038, 677.039, 677.232, 677.233, 677.234, 677.235, 677.236, 677.237, 677.238, 677.239, 679.235, 679.997  OM 356.992; OM 357.921; OM 357.932; OM 366.980; OM 366.988; OM 366.992; OM 366.997; (148-155kW)	01.84-12.98	 BM 677.032-035  BM 677.232-235	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1320  677.056, 677.057, 677.059, 677.256, 677.257, 677.258, 677.259  OM 356.992; OM 357.921; OM 357.932; OM 366.980; OM 366.988; OM 366.992; OM 366.997; (148-155kW)	01.84-12.98	 BM 677.056/057/256/257	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1520  677.022, 677.023, 677.024, 677.025, 677.026, 677.027, 677.028, 677.029, 677.222, 677.223, 677.224, 677.225, 677.226, 677.227, 677.228, 677.229  OM 356.990; OM 357.922; OM 357.930; OM 366.995; (150-155kW)	01.84-12.98	 BM 677.022-025/225	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1524  677.024, 679.022, 679.023, 679.024, 679.025, 679.026, 679.027, 679.028, 679.029, 679.222, 679.223, 679.224, 679.225, 679.226, 679.227, 679.228, 679.229  OM 356.999; OM 357.941; OM 357.947; OM 366.999; (170-177kW)	01.84-12.98	 BM 677.024	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1720  677.022, 677.024, 677.026  OM 357.922; OM 366.995; (150-155kW)	01.84-12.98	 OM 366.995	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7

NG

1417; 1617  616.014, 616.016, 616.017, 616.018, 616.115, 616.214, 616.315, 617.013, 617.014, 617.016, 617.018, 617.019, 617.111, 617.116, 617.117, 617.316, 617.414, 617.416, 617.418  OM 366.951; OM 366.952; (125kW)	08.73-09.96	 →5137784	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1419; 1420; 2219; 2220  616.046, 616.047, 616.048, 616.447, 616.448, 616.542, 619.011, 619.012, 619.014, 619.203, 619.204, 619.402, 619.411, 619.412, 619.414  OM 362.906; OM 362.909; OM 366.983; (141-150kW)	08.73-09.96		635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7



MERCEDES-BENZ

					
--	--	--	--	--	---

MERCEDES-BENZ

NG

1619; 1620  617.043, 617.044, 617.046, 617.047, 617.048, 617.049, 617.447, 617.448  OM 362.906; OM 362.909; OM 366.983; (141-150kW)	08.73-09.96	 BM 617.043-049  BM 617.447/448;  →5137784	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8 7
--	-------------	--	-------------	---	--

MERCEDES-BENZ

					
--	--	--	--	--	---

MERCEDES-BENZ


LK/LN2						
817  676.063, 676.263, 676.264  OM 356.948; OM 357.917; OM 366.969; (116-125kW)	01.84-12.98	 SA24494 01	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7
1120  677.073, 677.074, 677.273, 677.274, 677.275, 677.276  OM 356.993; OM 357.929; OM 366.993; (150-155kW)	01.84-12.98	 BM 677.073/074/273/274	635 3020 00	 135 0207 10  335 0103 16  500 0573 10	 8	7



635 3020 00 MERCEDES-
BENZ 2, 3, 4, 6



Liste des composants

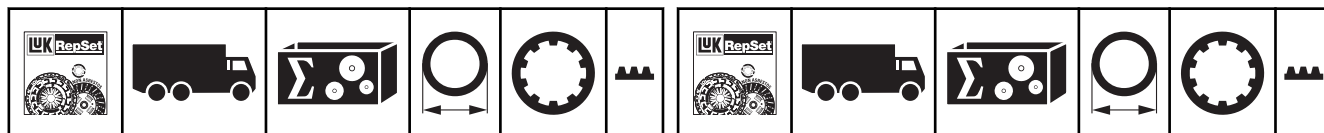

635 3020 00	MERCEDES-BENZ	 135 0207 10	350 TGFM		
		 335 0103 16	350 TZFN	1 3/4	10
		 500 0573 10			

**0...**

000 250 70 15	MERCEDES-BENZ	500 0573 10
001 250 22 15	MERCEDES-BENZ	500 0573 10
001 250 61 15	MERCEDES-BENZ	500 0573 10
004 250 24 04	MERCEDES-BENZ	135 0207 10
005 250 39 03	MERCEDES-BENZ	335 0103 16
005 250 40 03	MERCEDES-BENZ	335 0103 16
007 250 74 03	MERCEDES-BENZ	335 0103 16
013 250 57 03	MERCEDES-BENZ	335 0103 16
020 250 53 01	MERCEDES-BENZ	635 3020 00

1...

1250225	MERCEDES-BENZ	500 0573 10
---------	---------------	--------------------

A...

A 000 250 70 15	MERCEDES-BENZ	500 0573 10
A 001 250 22 15	MERCEDES-BENZ	500 0573 10
A 001 250 61 15	MERCEDES-BENZ	500 0573 10
A 004 250 24 04	MERCEDES-BENZ	135 0207 10
A 005 250 39 03	MERCEDES-BENZ	335 0103 16
A 005 250 40 03	MERCEDES-BENZ	335 0103 16
A 007 250 74 03	MERCEDES-BENZ	335 0103 16
A 013 250 57 03	MERCEDES-BENZ	335 0103 16
A 020 250 53 01	MERCEDES-BENZ	635 3020 00

